



SICK

8016404

Betriebsanleitung, Ergänzung DEUTSCH


Bitte lesen Sie die beiliegende Betriebsanleitung und diese Betriebsanleitungsergänzung sorgfältig durch.

Ergänzung/Abweichung der technischen Daten zur Betriebsanleitung WL4SLG:

Typ: **WL4SLG-3K2432VS01**

Artikelnr.: **1065697**

Versorgungsspannung: 10 VDC ... 24 VDC
 Schaltausgang: PNP, Pin2 hellerschaltend, Pin4 dunkelschaltend (antivalent)
 Zeitverzögerung: 16 ms (+/- 5%) On Delay
 Ausgangsstrom I_{max.}: < 50 mA
 Ansprechzeit: < 0,330 ms
 Schaltfrequenz: 1500 Hz
 Umgebungstemperatur Betrieb: -10°C ... 50°C

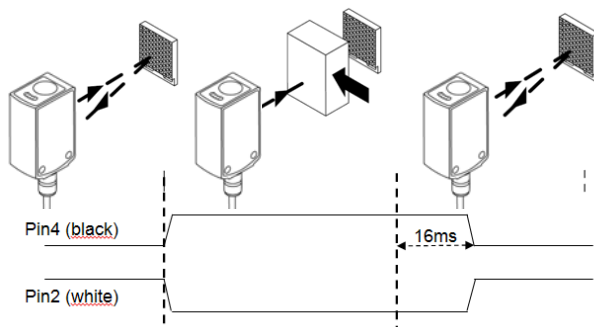

Irrtümer und Änderungen vorbehalten
SICK AG, D-79183 Waldkirch, Erwin-Sick-Str. 1, www.sick.com

Operating Instruction, Supplement ENGLISH


Please read the enclosed operating instruction and this operating instruction supplement carefully.

Supplement/deviation of technical data of the operating instructions WL4SLG:

Model Name: **WL4SLG-3K2432VS01**

Part No.: **1065697**

Supply voltage: 10 VDC ... 24 VDC
 Output type: PNP, Pin2 light switching, Pin4 dark switching (antivalent)
 Delay: 16 ms (+/-5%) On Delay
 Output current I_{max.}: < 50 mA
 Response time: < 0,330 ms
 Switching frequency: 1500 Hz
 Ambient operating temperatur: -10°C ... 50°C

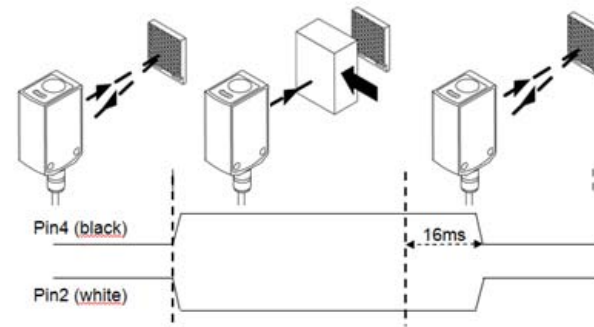

Subject to change without notice.
SICK AG, D-79183 Waldkirch, Erwin-Sick-Str. 1, www.sick.com