



SICK

8015999

Betriebsanleitung, Ergänzung DEUTSCH

Bitte lesen Sie die beiliegende Betriebsanleitung und diese Betriebsanleitungsergänzung sorgfältig durch.

Ergänzung/Abweichung der technischen Daten zur Betriebsanleitung WTB27-3 RT DC:

Typ: WTB27-3P1161S23

Artikelnr.: 1045970

Schaltabstand max.: 30...2000 mm auf weiß (90% Remission)
Lichtart: Rotlicht, PinPoint-LED
Ansprechzeit: $\leq 3,3$ ms
Schaltfrequenz: 150 Hz
Abmessungen (B x H x T): 24,6 mm x 79,5 mm x 43,3 mm

Achtung!


Montage mit Distanzstück

Sensor darf nur mit Distanzstück
(siehe rechts) montiert werden.

Warning!

Installation with a spacer

The sensor has to be installed
with a spacer only (see drawing).

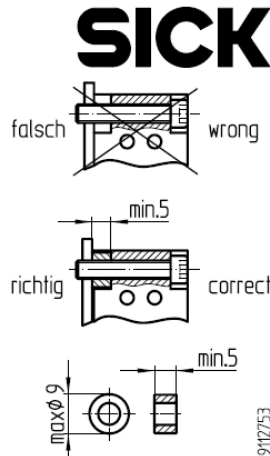

Irrtümer und Änderungen vorbehalten

SICK AG, D-79183 Waldkirch, Erwin-Sick-Str. 1, www.sick.com

Operating Instruction, Supplement ENGLISH

Please read the enclosed operating instruction and this operating instruction supplement carefully.

Supplement/deviation of technical data of the operating instructions WTB27-3 RT DC:

Model Name: WTB27-3P1161S23

Part No.: 1045970

Sensing distance, typ. max.: 30...2000 mm on white (90% Remission)
Type of light: red light, PinPoint LED
Response time: ≤ 3.3 ms
Switching frequency: 150 Hz
Dimensions (B x H x T): 24.6 mm x 79.5 mm x 43.3 mm

Achtung!


Montage mit Distanzstück

Sensor darf nur mit Distanzstück
(siehe rechts) montiert werden.

Warning!

Installation with a spacer

The sensor has to be installed
with a spacer only (see drawing).

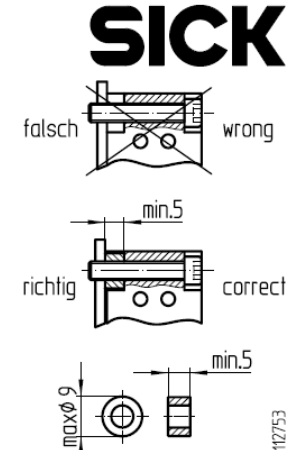

Subject to change without notice.

SICK AG, D-79183 Waldkirch, Erwin-Sick-Str. 1, www.sick.com