


Type code

Type code

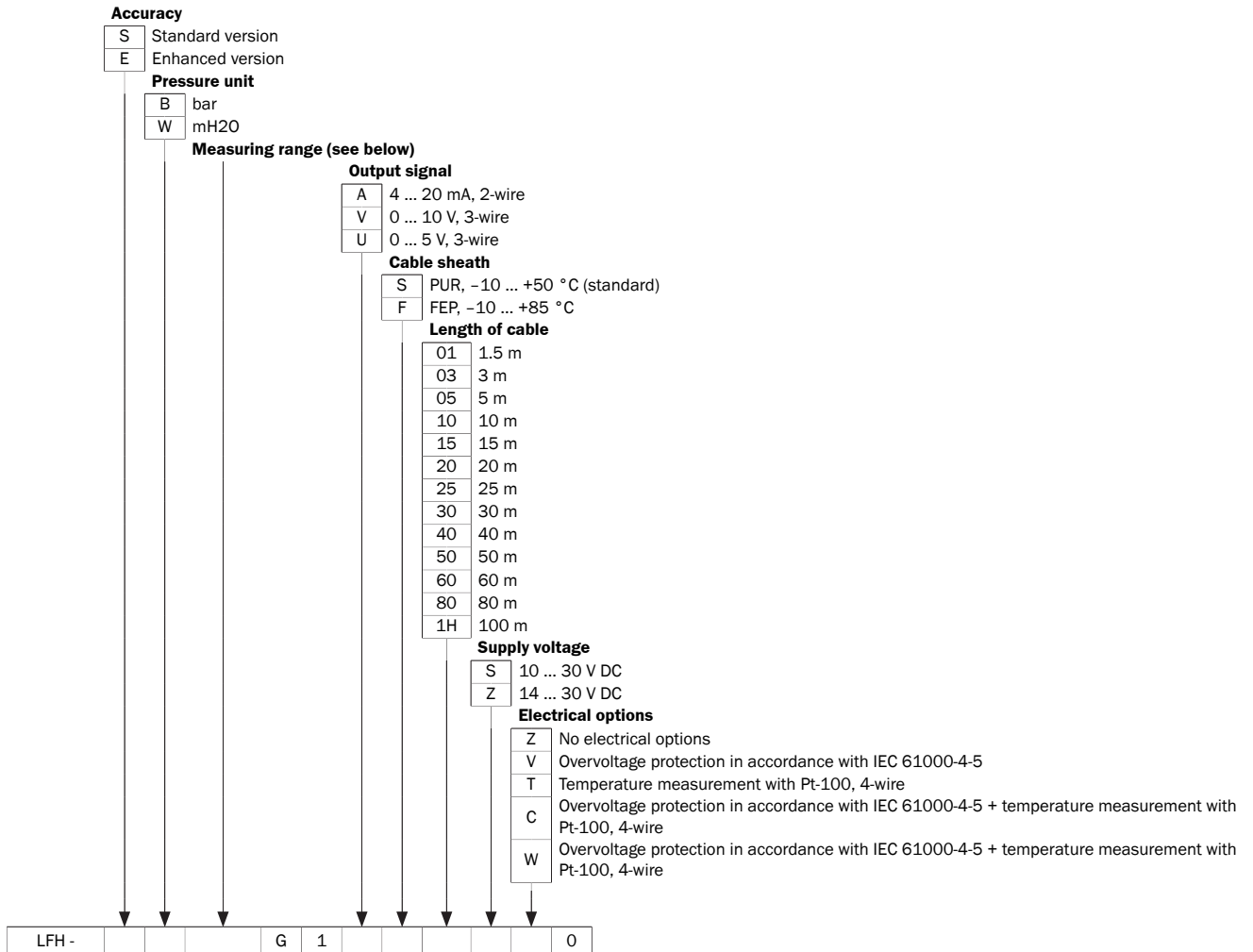

Not all variants of the type code can be combined!

Measuring range

Bar / gauge pressure	
X10	0 ... 0.1 bar
X16	0 ... 0.16 bar
X25	0 ... 0.25 bar
X40	0 ... 0.4 bar
X60	0 ... 0.6 bar
1X0	0 ... 1 bar
1X6	0 ... 1.6 bar
2X5	0 ... 2.5 bar
4X0	0 ... 4 bar
6X0	0 ... 6 bar
010	0 ... 10 bar
016	0 ... 16 bar
025	0 ... 25 bar

MH ₂ O / gauge pressure	
1X0	0 ... 1 mH ₂ O
1X6	0 ... 1.6 mH ₂ O
2X5	0 ... 2.5 mH ₂ O
4X0	0 ... 4 mH ₂ O
6X0	0 ... 6 mH ₂ O
010	0 ... 10 mH ₂ O
016	0 ... 16 mH ₂ O
025	0 ... 25 mH ₂ O
040	0 ... 40 mH ₂ O
060	0 ... 60 mH ₂ O
100	0 ... 100 mH ₂ O
160	0 ... 160 mH ₂ O
250	0 ... 250 mH ₂ O

