

PNS75-079S05

Reichweite bei Umlenkung mit Edelstahlspiegel

D

SICK AG • Industrial Safety Systems
 Erwin-Sick-Straße 1 • D-79183 Waldkirch
 Germany • www.sick.com
 8012973/2009-01-21 • CUMC/KE
 Printed in Germany (2009-01) • All rights reserved.




Sicherheits-Lichtvorhang/Auflösung in mm

	A	B	C	D
C4000 Basic	14	30	-	-
C4000 Basic Plus	14	30	-	-
C4000 Micro	14	30	-	-
C4000 Eco	14	30	-	-
C4000 Standard	-	-	14	20/30/40
C4000 Advanced	-	-	14	20/30/40
C4000 Fusion	-	-	-	20
C4000 Select	-	-	-	30
M4000 Standard Curtain	-	-	14	30
M4000 Advanced Curtain	-	-	14	30



Umlenkung mit 1 Edelstahlspiegel #1046075

Reichweite = a+b (m)

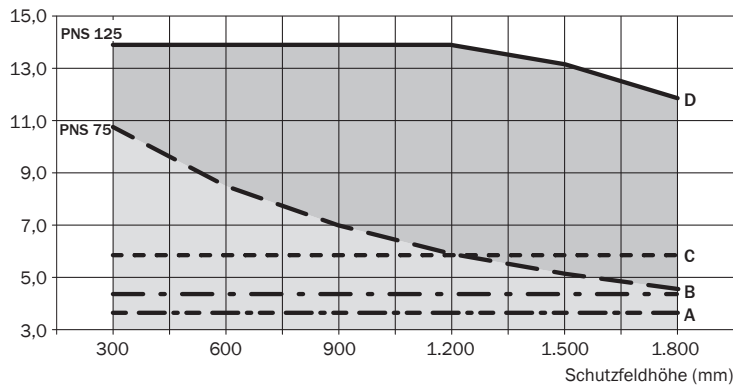

Ablesebeispiel:
 (Umlenkung mit einem Edelstahlspiegel)

C4000 Standard
 1.200 mm (C): 5,9 m → PNS75
 (ab 1.200 mm → PNS125)


C4000 Standard
 600 mm (C): 7 m → PNS75

C4000 Standard
 600 mm (C): 13 m → PNS125



Umlenkung mit 2 Edelstahlspiegeln # 1046075

Reichweite = a+b+c (m)

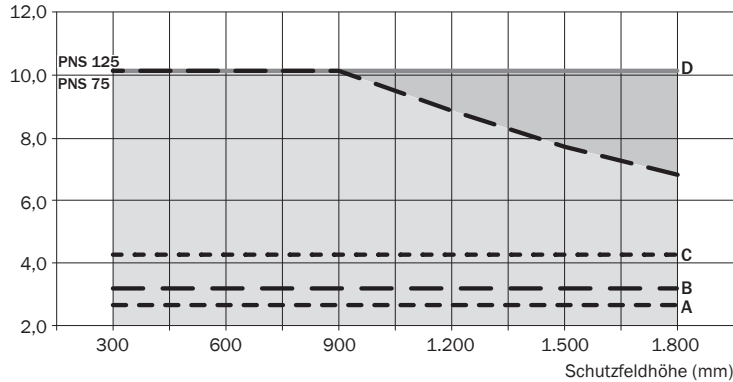

PNS75-079S05

Range of deflection with stainless steel deflector mirror

GB

SICK AG • Industrial Safety Systems
 Erwin-Sick-Straße 1 • D-79183 Waldkirch
 Germany • www.sick.com
 8012973/2009-01-21 • CUMC/KE
 Printed in Germany (2009-01) • All rights reserved.




Safety light curtain/resolution in mm

	A	B	C	D
C4000 Basic	14	30	-	-
C4000 Basic Plus	14	30	-	-
C4000 Micro	14	30	-	-
C4000 Eco	14	30	-	-
C4000 Standard	-	-	14	20/30/40
C4000 Advanced	-	-	14	20/30/40
C4000 Fusion	-	-	-	20
C4000 Select	-	-	-	30
M4000 Standard Curtain	-	-	14	30
M4000 Advanced Curtain	-	-	14	30



Deflection with 1 stainless steel mirror #1046075

Range = a+b (m)

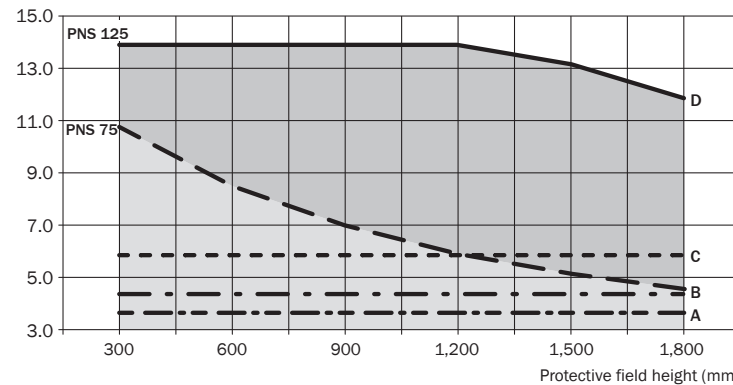

Example:
 (deflection with 1 stainless steel mirror)

C4000 Standard
 1,200 mm (C): 5,9 m → PNS75
 (more than 1,200 mm → PNS125)

C4000 Standard
 600 mm (C): 7 m → PNS75

C4000 Standard
 600 mm (C): 13 m → PNS125



Deflection with 2 stainless steel mirrors #1046075

Range = a+b+c (m)

